

## Premier Performers

### Swagelok Componentry delivers

**proven productivity and profitability – consistently and reliably – no matter how challenging your fluid-system applications or operating environments.**

And no products keep you safer, with superior protection against costly and dangerous leakage, on the toughest Oil and Gas, Power Generation, Chemical, Refining, Steel, and General Industrial jobs.

*Since 1947, Swagelok tube fittings, valves, gauges, hoses, and tubing have been genuine difference-makers to help positively impact your Bottom-Line health and Top-Line growth. Better by design and made with premium-quality materials to the industry's highest standards, Swagelok products are simple to install and maintain... and backed by the renowned Swagelok Limited Lifetime Warranty.*



### 60-Series Ball Valves

- Operational fully opened or fully closed
- API 641 Test Certificate for Methane Service
- Unique, swing-out design enables fast and easy in-line maintenance

[CLICK TO VIEW OUR 60-SERIES BALL VALVES](#)



### GB-Series Ball Valves

- Bi-directional, full flow
- For pressures up to 6000 psig
- Mechanically locked end screws will not rotate when installing/removing end connections
- No O-Rings required, so zero compatibility issues with most hydrocarbons, solvents, or strong acids

[CLICK TO VIEW OUR GB-SERIES BALL VALVES](#)



### Industrial Hoses

- 24 available styles in sizes 1/8" to 2", with multiple end connections, tags, and covers
- 5 cores offered: All-Metal, Fluoropolymer, Polyethylene, Nylon, Rubber
- Working pressures up to 6000 psi and temperature ranges -325° F to 1,000° F
- Swagelok Hose Advisories available to audit current selection, sizing, storage, and routing practices

[CLICK TO VIEW OUR INDUSTRIAL HOSES](#)



### Pressure Regulators

- Maintain pressure while minimizing droop and creep
- A wide array of styles: Analytical/Instrumentation, Process, High-Purity/High-Flow, Vaporizing, Gas Cylinder Changeover, Tank Blanketing

[CLICK TO VIEW OUR PRESSURE REGULATORS](#)



### Gauges

- Stainless steel and reinforced thermoplastic construction
- Made in accordance with ASME B40.100, EN, and JIS standards
- Safely/confidently monitor vacuum and positive system pressures up to 15000 psi, 1000 bar, or 100 MPa

[CLICK TO VIEW OUR GAUGES](#)



### FK/IPT Medium/High-Pressure Solutions

- Exceptional for test stands, instrumentation and hydraulic control panels, and more
- Fittings, Tubing, Low-E Valves... all for working pressures up to 20000 psig
- Hydrogen application components

[CLICK TO VIEW OUR FK/IPT MEDIUM/HIGH-PRESSURE SOLUTIONS](#)


**For additional information on all Swagelok products and strategic support services, contact:**

**Tony Del Bianco,**  
Direct Sales Representative



[tony.delbianco@swagelok.com](mailto:tony.delbianco@swagelok.com)

**Gary Osman,**  
Field Services Engineer

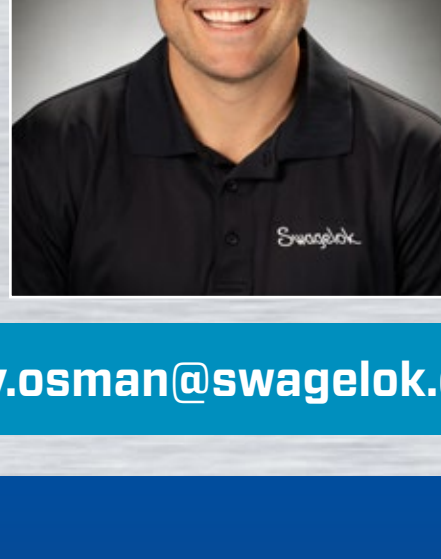

[gary.osman@swagelok.com](mailto:gary.osman@swagelok.com)

## WE DELIVER DIFFERENCE-MAKING SOLUTIONS:

[Products](#) | [Strategic Support Services](#) | [Application Know-How](#)



*The Brand. The Inventory. The Expertise.*

**WE'RE YOUR SWAGELOK FLUID-SYSTEM SOLUTIONS PROVIDER**



**Industry-Best Componentry**




**Masterful Custom Fabrication**




**Expert Safety Training**




**Extensive Energy Evaluations**

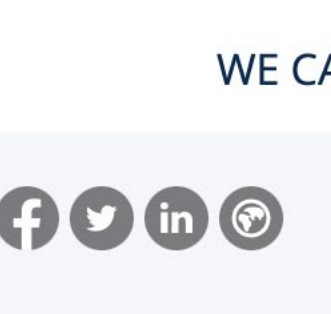


**Unparalleled Application Knowledge**

 


**Comprehensive Hose Advisories**

 


**Proven Inventory Management Support**

 

**Genuine Swagelok Tool Rentals**

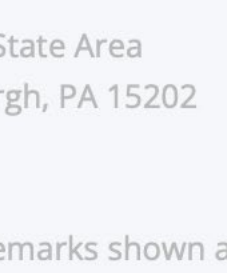

**WE CAN HELP YOU SAVE TIME, MONEY, AND WORRY:**

 

[Share](#)

[Tweet](#)

[Share](#)

[Forward](#)

Swagelok Pittsburgh | Tri-State Area  
49 Meade Avenue, Pittsburgh, PA 15202  
412.761.3212

All service marks and trademarks shown are owned and registered by Swagelok Company. © 2023 Swagelok Company. [www.swagelok.com](http://www.swagelok.com)

You are receiving this email as a valued contact of Swagelok Pittsburgh | Tri-State Area.

[Preferences](#) | [Unsubscribe](#)